


Application example

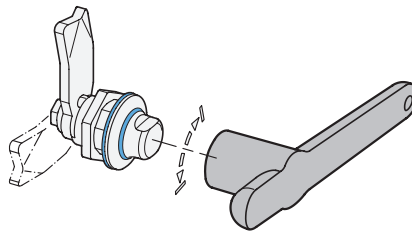

- 2** Type
- SW9** With two wrench flats A/F9
 - SW13** With two wrench flats A/F13

Metric table



Dimensions in: millimeters - inches

| l_1 | d_1 | d_2 | h | l_2 | A/F in mm | For cam latches |
|------------|------------|-----------|--------------|------------|-----------|-----------------------|
| 82 3.23 | 23 0.91 | 5 0.20 | 42.7 1.68 | 35 1.38 | 9 | GN 1150 |
| 82 3.23 | 23 0.91 | 5 0.20 | 42.7 1.68 | 35 1.38 | 13 | GN 1150 / GN 115-AZ13 |

Specification



- Plastic Technopolymer (Polyamide PA) **PA**
- Glass fiber reinforced
- Blue **BL**
- Plastic Characteristics → page QVX
- RoHS

Information

Socket keys GN 1151 can be used to operate latches in hygienic areas. The material used protects the drive surface from damage.

The bore d_2 serves for storing the socket key near the place of use, for example, or can be used to attach a key ring or retaining cable to prevent loss.

see also...

- Product Family [Hygienic Design](#) → page QVX
- Cam Latches GN 1150 (Stainless Steel, Operating Side in [Hygienic Design](#)) → page QVX
- Cam Latches GN 1150 (Stainless Steel, Operating and Latch Arm Side in [Hygienic Design](#)) → page QVX
- Cam Latches GN 115 (Stainless Steel, Protection Class IP 69K) → page QVX
- Retaining Cables GN 111.8 (Stainless Steel AISI 316) → page QVX

How to order

GN 1151-82-SW9-PA-BL

| | |
|----------|--------------|
| 1 | Length l_1 |
| 2 | Type |
| 3 | Material |
| 4 | Color |