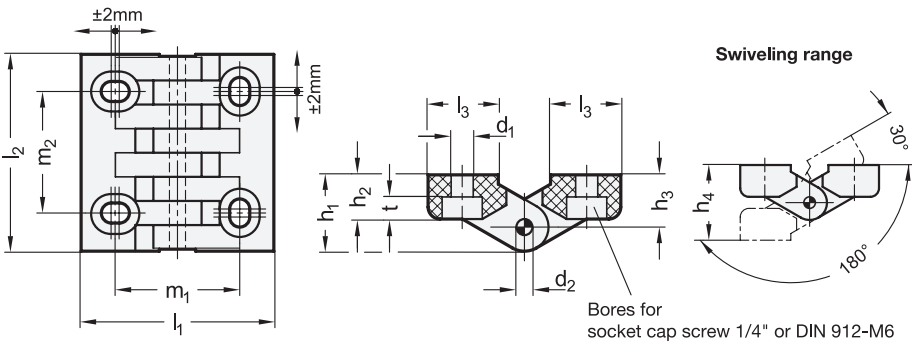


- 3** Type
- H** Vertical slots
 - B** Horizontal slots
 - HB** Horizontal and vertical slots

Metric table

Dimensions in: millimeters - inches											
1	2										
l_1	l_2	d_1	d_2	h_1	h_2	h_3	h_4	l_3	m_1	m_2	t
64	65	6.5	5	23	13.5	15	30	24	40	40	6.5
2.52	2.56	0.26	0.20	0.91	0.53	0.59	1.18	0.94	1.57	1.57	0.26

Specification

- Body
 - Plastic
 - Technopolymer (Polyamide PA)
 - Black, matte finish
 - Temperature resistant up to 176 °F (80 °C)
- Pin
 - Stainless steel AISI 303
- Load Rating Information → page 2095
- Plastic Characteristics → page 2135
- Stainless Steel Characteristics → page 2143
- RoHS compliant

Information

- EN 151.4 hinges are adjustable vertically or horizontally along the slots and are fastened with cylinder head screws.
- see also...
- Product Family Standard Parts for Profile Systems → page 18
 - List of Hinge Types → page 1324
 - Adjustable Alignment Hinges GN 127 (Zinc Die-Cast) → page 1404
 - Hinges EN 236 (Technopolymer Plastic, Adjustable) → www.jwwinco.com
 - Adjustable Alignment Hinges GN 238 (Zinc Die-Cast) → page 1402

How to order		1	Width l_1
		2	Length l_2
		3	Type
EN 151.4-64-65-HB			