


Metric

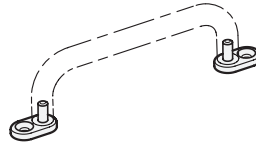

Metric table

Dimensions in: millimeters / inches

d ₁	d ₂	b	d ₃ ^{+0.2 +0.5}	Length l	m	s	t	Countersunk screw DIN 7991	For cabinet U-handles
8 0.31	M 4	10 0.39	4 0.157	20 0.79	10 0.39	3 0.12	7 0.28	M 4 x 10	GN 425-8-...
10 0.39	M 5	12 0.47	5 0.197	24 0.94	12 0.47	4 0.16	8 0.31	M 5 x 12	GN 425-10-... / GN 425.1-10-...
12 0.47	M 6	15 0.59	6 0.236	30 1.18	15 0.59	4.5 0.18	9.5 0.37	M 6 x 14	GN 425-12-... / GN 425.1-12-... / GN 435-12-...
16 0.63	M 6	18 0.71	6 0.236	34 1.34	16 0.63	4.5 0.18	9.5 0.37	M 6 x 14	GN 425-16-... / GN 435-16-...
20 0.79	M 6	22 0.87	6 0.236	40 1.57	18 0.71	4.5 0.18	9.5 0.37	M 6 x 14	GN 565-20-... / GN 565.5-20-...
20 0.79	M 8	22 0.87	8 0.315	42 1.65	20 0.79	6 0.24	12 0.47	M 8 x 18	GN 426-20-... / GN 426.1-20-...
26 1.02	M 8	28 1.10	8 0.315	52 2.05	24 0.94	6 0.24	12 0.47	M 8 x 18	GN 565-26-...
28 1.10	M 10	30 1.18	10 0.394	56 2.20	26 1.02	6.5 0.26	13.5 0.53	M 10 x 20	GN 426-28-... / GN 426.1-28-...

Specification

Plates

Zinc die-cast
Powder coated

ZD

- Black, RAL 9005, textured finish
- Silver, RAL 9006, textured finish

- **SW**
- **SR**

Countersunk screws DIN 7991

Steel, zinc plated, blue passivated finish

RoHS

Mounting plate sets GN 181 make it possible to mount different cabinet U-handles and tubular handles with an internal thread from the operator's side. The position placement of the mounting plates is flexible, allowing a sideways offset or mounting with different drill hole spacings. A mounting plate set consists of 2 counterbored plates and 2 countersunk screws.

see also...

Page

GN 425 Cabinet U-Handles (Steel / Aluminum / Stainless Steel)	QVX
GN 425.1 Cabinet U-Handles (Steel / Aluminum / Stainless Steel)	QVX
GN 565 Cabinet U-Handles (Aluminum)	QVX
GN 565.5 Cabinet U-Handles (Stainless Steel)	QVX
GN 426 Cabinet U-Handles (Aluminum)	QVX

How to order

1 Material
2 Handle diameter d ₁
3 Thread d ₂
4 Finish

GN 181-ZD-28-M10-SW

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4

