

GN 187.1


Steel / Stainless Steel

Guide Housings

for GN 187.4 Serrated Locking Plates



JWWINCO
A Ganter Company

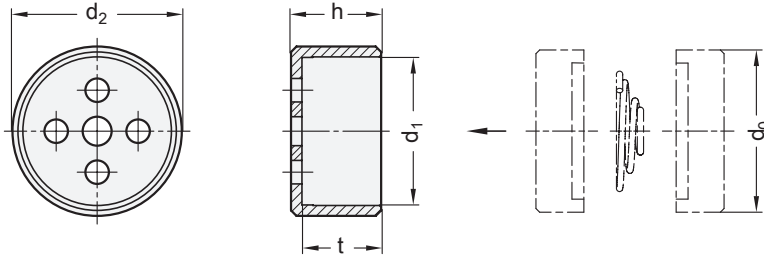

SS Stainless Steel

Metric table



Dimensions in: millimeters - inches

d_1 ^{+0.2} / _{+0.3}	d_2 -0.5	h	t	For GN 187.4 serrated locking plates - d_0
22 0.87	26 1.02	14.5 0.57	12.5 0.49	22 0.87
27 1.06	31 1.22	16.5 0.65	14.5 0.57	27 1.06
32 1.26	36 1.42	19.5 0.77	17.5 0.69	32 1.26
40 1.57	44 1.73	24.5 0.96	22.5 0.89	40 1.57

Specification



- Steel, blackened finish **ST**
- Stainless steel AISI 303 **NI**
- *Stainless Steel Characteristics* → page 2143
- [RoHS compliant](#)

Information

GN 187.1 guide housings are utilized with GN 187.4 serrated locking plates.

see also...

- *Serrated Locking Plates GN 187.4* → page 1160

How to order

GN 187.1-27-NI

1 Inner diameter d_1

2 Material