


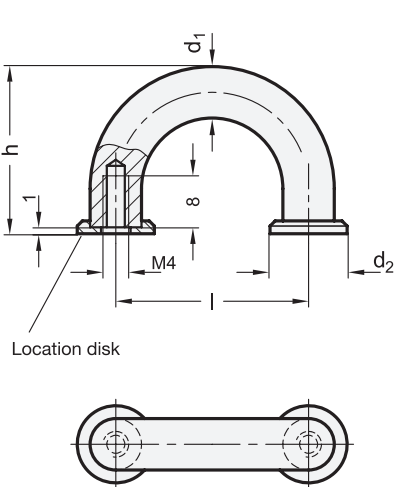

Metric table

1 d₁	2 Length l ±0.25	d₂	h
8 0.31	30 1.18	12 0.47	26 1.02
10 0.39	40 1.57	15 0.59	31 1.22

Specification

GN 224.1

Steel

• Chrome plated

• Location disks

Zinc die-cast, nickel-plated finish

3

CR

GN 224.5

Stainless steel AISI 304

• Matte shot-blasted finish

• Location disks

Stainless Steel AISI 303

RoHS

On request

• Various metric size fasteners and kit packaging

Finger grip handles GN 224.5 are supplied with two location disks. They guarantee a perfect location even with oversize mounting holes in the cabinet. The disks are supplied loose.

see also...

EN 224.3

Finger Grip Handles (Plastic)

Page

QVX

Technical Information

Stainless Steel Characteristics

QVX