


Metric

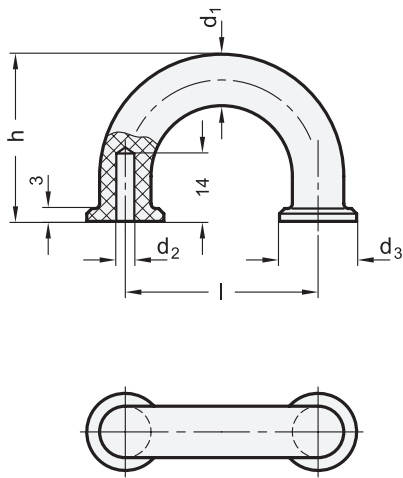

Metric table

1 d ₁	2 Length l		3 d ₂	d ₃	h
	Nominal dimension	Actual dimension			
9 0.35	30 1.18	29.5 1.16	B 3.5	12 0.47	27 1.06
10 0.39	40 1.57	39.5 1.56	B 3.5	15 0.59	33.5 1.32

Specification

- Plastic, Polyamide (PA)
- Operating temperature

-22 °F to 212 °F (-30 °C to +100 °C)
- Color

● SW

● OR

● GR

● RT

● WS

- Black, RAL 9005, matte finish

- Orange, RAL 2004, matte finish

- Gray, RAL 7035, matte finish

- Red, RAL 3000, matte finish

- White, RAL 9002, matte finish
- RoHS
- Finger grip handles EN 224.3 with bore hole B 3.5 mm are intended for mounting with self-tapping screws, such as DIN ISO 7049 pan head tapping screws of thread size ST 4.2 mm.
- | see also... | Page |
|--|------|
| GN 224.1 Finger Grip Handles (Steel) | QVX |
| GN 224.5 Finger Grip Handles (Stainless Steel) | QVX |
- | Technical Information | |
|-------------------------|-----|
| Strength Values | QVX |
| Plastic Characteristics | QVX |
- | How to order | 1 | Handle diameter d ₁ |
|------------------------|---|--------------------------------|
| | 2 | Length l |
| | 3 | Bore d ₂ |
| | 4 | Color |
| EN 224.3-10-40-B3.5-SW | | |
- www.jwwinco.com | 1-800-877-8351

 WARNING: Cancer and Reproductive Harm — www.P65Warnings.ca.gov

1