


Inch

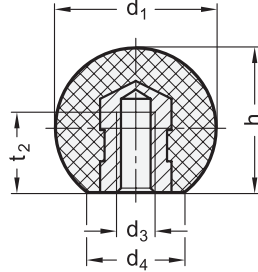

4 Type

E With tapped insert

Inch table

Dimensions in: inches / millimeters

d₁	d₃	d₄ ≈	h ≈	t₂ min.
0.79 20	10 x 24	0.47 12	0.71 18	0.375 9.525
0.79 20	1/4 x 20	0.47 12	0.71 18	0.375 9.525
0.98 25	1/4 x 20	0.59 15	0.89 22.5	0.375 9.525
0.98 25	5/16 x 18	0.59 15	0.89 22.5	0.500 12.7
1.26 32	5/16 x 18	0.71 18	1.14 29	0.500 12.7
1.26 32	3/8 x 16	0.71 18	1.14 29	0.625 15.875
1.57 40	3/8 x 16	0.87 22	1.46 37	0.625 15.875
1.57 40	1/2 x 13	0.87 22	1.46 37	0.750 19.05

Specification

Knob

- Plastic, Phenolic (PF)
- Flash removed and polished
- Black, shiny finish

1

5

KU

Tapped insert

Brass

MS

RoHS

Since there are no parting lines in the middle of the ball, the ball knob GN 319 is an excellent choice for user friendly applications.

see also...

	Page
DIN 319 Ball Knobs (Tapped Insert Type, Metric Size)	QVX
DIN 319 Ball Knobs (Press-On Type)	QVX

Technical Information

Plastic Characteristics	QVX
-------------------------	-----

How to order

1 Material
2 Ball diameter d ₁
3 Thread d ₃
4 Type
5 Insert material

GN 319-KU-25-1/4x20-E-MS

1 2 3 4 5

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4

