


Metric

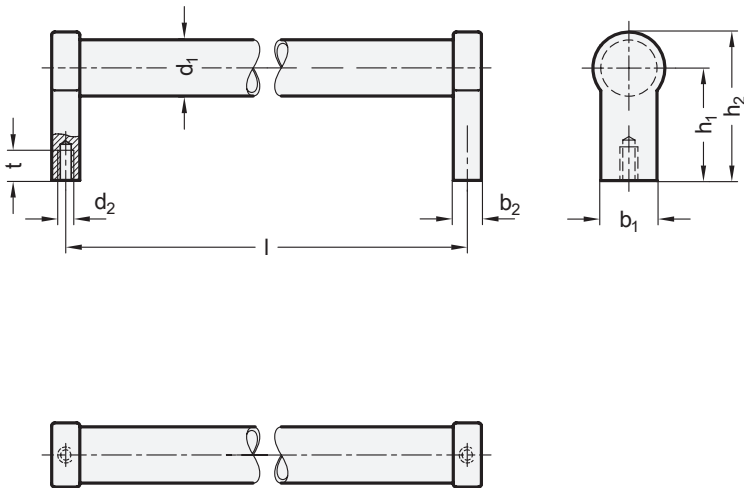

SS
Stainless Steel

Metric table

1		2		Dimensions in: millimeters / inches									
d ₁	Length l						b ₁	b ₂	d ₂	h ₁	h ₂	t min.	
28	200	250	300	400	500	600	25	14	M 8	50	66	15	
1.10	7.87	9.84	11.81	15.75	19.69	23.62	0.98	0.55		1.97	2.60	0.59	

Specification

Handle tube

Stainless steel AISI 304, wall thickness 2 mm
Ground, matte shiny finish

Handle legs

Stainless steel precision casting AISI CF-8
Matte shot-blasted finish

RoHS

The tube of tubular handles GN 333.7 is pressed together with the handle legs.

see also...	Page
GN 333.6 Tubular Handles (Angled)	QVX
GN 426.5 Cabinet U-Handles (Stainless Steel)	QVX
GN 565.5 Cabinet U-Handles (Stainless Steel, Mounting from the Back or from the Operator's Side)	QVX
GN 666.5 Tubular Grip Handles (Stainless Steel, Mounting from the Back)	QVX
GN 333.1 Tubular Handles (Aluminium, Zinc Die-Cast)	QVX

Technical Information

Load Capacity Information	QVX
Stainless Steel Characteristics	QVX

How to order	1	Handle diameter d ₁
	2	Length l
GN 333.7-28-400		