


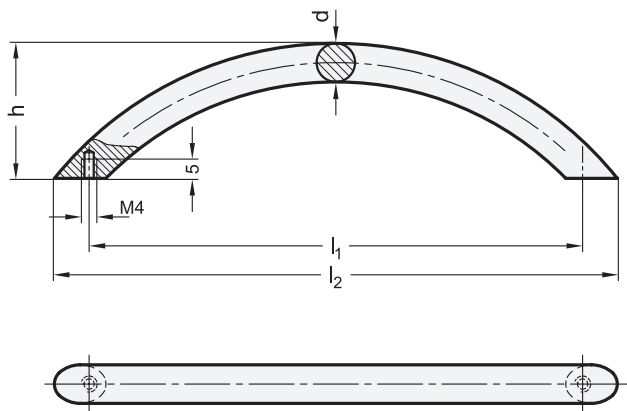

Metric table

Dimensions in: millimeters / inches			
d	l ₁	l ₂ ≈	h ≈
10 0.39	64 ±0.25 2.52 ±0.01	75 2.95	35 1.38
10 0.39	96 ±0.25 3.78 ±0.01	111 4.37	35 1.38
10 0.39	128 ±0.25 5.04 ±0.01	146 5.75	35 1.38
10 0.39	160 ±0.25 6.30 ±0.01	181 7.13	35 1.38
10 0.39	192 ±0.35 7.56 ±0.014	219 8.62	35 1.38

Specification

GN 424.1

Steel

Powder coated

• Black, RAL 9005, textured finish

• Silver, RAL 9006, textured finish

GN 424.5

Stainless steel AISI 303

Matte brushed finish

RoHS

On request

• Various metric size fasteners and kit packaging

● SW

● SR

Arched handles GN 424.5 are preferably used for such applications where easy sliding of folding doors or cabinet drawers can be operated with a single finger.

Their shape blends well with modern design.

see also...

GN 565.4 Arched Pull Handles

(Aluminium, Mounting from the Back or from the Operator's Side)

Page

QVX

Technical Information

Load Capacity Information

Stainless Steel Characteristics

QVX

QVX