


Metric

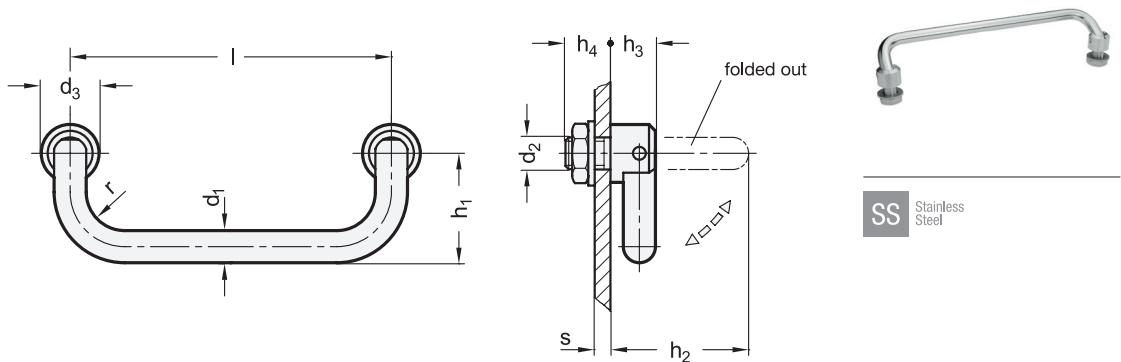

Metric table

d ₁		Length l ±0.25			d ₂	d ₃	h ₁	h ₂	h ₃	h ₄	r	s max.
Stainless steel	Steel											
6	-	55*	64	88*	M 6	12	21	27.5	9.5	10	6	4
0.24	-	2.17	2.52	3.46		0.47	0.83	1.08	0.37	0.39	0.24	0.16
10	10	100	120	180	M 10 x 1	18	34	43	14	14	12	6
0.39	0.39	3.94	4.72	7.09		0.71	1.34	1.69	0.55	0.55	0.47	0.24

* suitable for 19" rack and enclosure layout

Specification	1	4
Handle		
• Steel	ST	
• Chrome plated		CR
• Stainless steel AISI 303	NI	
• Matte shot-blasted finish		GS
Hex nuts ISO 8675		
Stainless Steel A2		
Washers DIN 125		
Stainless steel A2		
RoHS		

Folding handles GN 425.2 are used in such applications where minimal protrusion is required.
In both positions the handle is retained by a spring-loaded detent pin.

see also...	Page
GN 425.5 Folding Handles (Steel, Plastic Attachment Part)	QVX
GN 425.8 Folding Handles with Recessed Tray (with Handle Held or Spring Return)	QVX
GN 425.9 Folding Handles (Stainless Steel, with / without Retaining Spring)	QVX
EN 825.1 Folding Handles (Plastic, with Spring-Loaded Return)	QVX

Technical Information	
Load Rating Information	QVX
Stainless Steel Characteristics	QVX

How to order (Steel)	1	Material
	2	Handle width d ₁
	3	Length l
	4	Finish
GN 425.2-ST-10-120-CR		

How to order (Stainless steel)	1	Material
	2	Handle width d ₁
	3	Length l
	4	Finish
GN 425.2-NI-10-180-GS		