


Metric

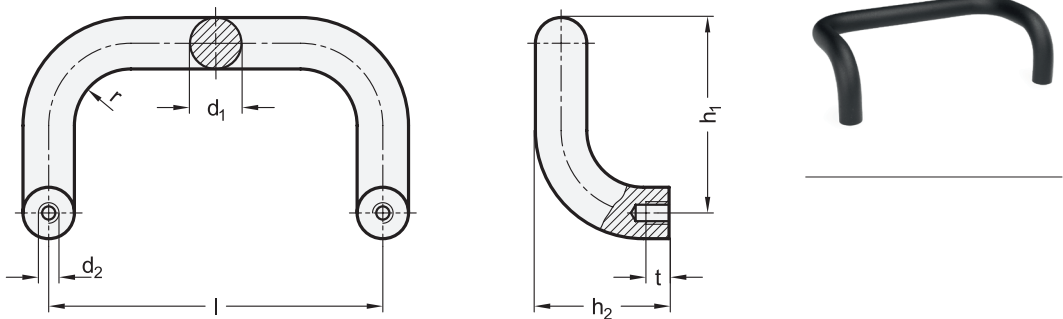

Metric table

Dimensions in: millimeters / inches						
d ₁	Length l	d ₂	h ₁	h ₂	r	t min.
20 0.79	200 7.87	M 8	105 4.13	68 2.68	22 0.87	15 0.59
20 0.79	300 11.81	M 8	105 4.13	68 2.68	22 0.87	15 0.59
28 1.10	250 9.84	M 10	125 4.92	78 3.07	32 1.26	15 0.59
28 1.10	350 13.78	M 10	125 4.92	78 3.07	32 1.26	15 0.59
28 1.10	500 19.69	M 10	125 4.92	78 3.07	32 1.26	15 0.59

Specification

Aluminum

- Powder coated
 - Black, RAL 9005, textured finish
 - Silver, RAL 9006, textured finish
- Plain, tumbled finish

RoHS

On request

- Various metric size fasteners and kit packaging

1

4

AL

● SW

● SR

○ BL

Cabinet U-handles GN 426.1 are manufactured from a bent aluminum profile.

see also...	Page
GN 426.4 Cabinet U-Handles (Mounting from the Operator's Side)	QVX
GN 565.2 Angled Cabinet U-Handles (Mounting from the Back or from the Operator's Side)	QVX
GN 425.1 Cabinet U-Handles (Ø 8, 10, 12 mm, Offset Aluminum / Stainless Steel, Angled)	QVX
GN 333 Tubular Handles (Angled)	QVX

Technical Information
Load Capacity Information
QVX
Accessory
GN 181 Mounting Plate Sets (Mounting from the Operator's Side)
QVX

How to order

1

2

3

4

GN 426.1-AL-28-250-SW

1

2

3

4

Material

Handle diameter d₁

Length l

Finish