 



1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4




Metric

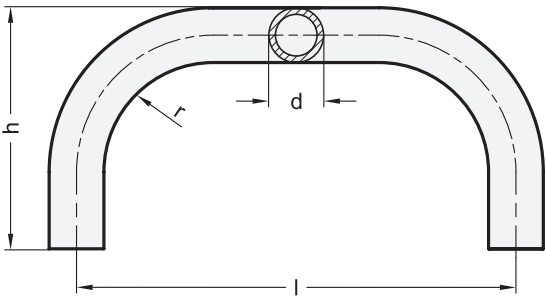

4 Type

A Simply curved, 90°

Application example

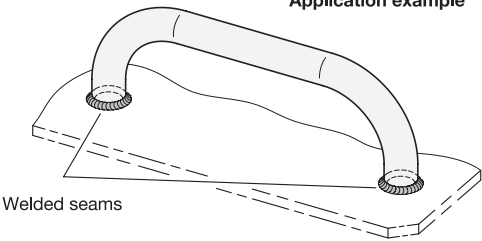

Metric table

2		3								Dimensions in: millimeters / inches		
d		Length l ±1.5				h ±1.5	r	s				
20	0.79	150	200	250	300	400	90	40	3			
		5.91	7.87	9.84	11.81	15.75	3.54	1.57	0.12			
25	0.98	200	250	300	400	500	110	50	3			
		7.87	9.84	11.81	15.75	19.69	4.33	1.97	0.12			
30	1.18	300	350	400	500	600	130	60	3			
		11.81	13.78	15.75	19.69	23.62	5.12	2.36	0.12			

Specification

Steel

Plain finish, oiled

RoHS

1

ST

Cabinet U-handles GN 426.3 are manufactured from hollow seamless steel tubing.

see also...

GN 425.3 Cabinet U-Handles (Steel / Stainless Steel)

Page

QVX

How to order

1

2

3

4

GN 426.3-ST-25-250-A

1

2

3

4

Material

Handle diameter d

Length l

Type