


Metric

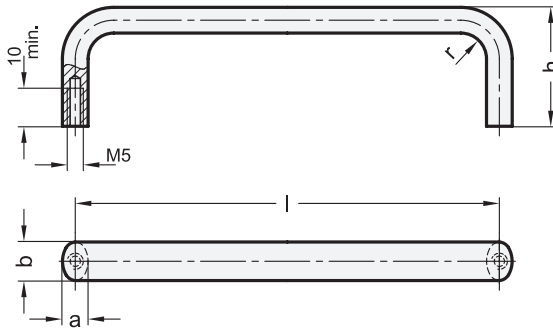

SS Stainless Steel

Metric table

b	Length l ±0.25	a	h	r
12 0.47	55* 2.17	8 0.31	40 1.57	8 0.31
12 0.47	88* 3.46	8 0.31	40 1.57	8 0.31
12 0.47	100 3.94	8 0.31	40 1.57	8 0.31
12 0.47	120* 4.72	8 0.31	40 1.57	8 0.31
12 0.47	180* 7.09	8 0.31	40 1.57	8 0.31
12 0.47	200 7.87	8 0.31	40 1.57	8 0.31
12 0.47	235* 9.25	8 0.31	40 1.57	8 0.31

Dimensions in: millimeters / inches

* Suitable for 19" rack and enclosure layout

Specification

GN 427

Aluminum

- Powder coated
 - Black, RAL 9005, textured finish ● **SW**
 - Silver, RAL 9006, textured finish ● **SR**
- Anodized finish, natural color ● **EL**

GN 427

Stainless steel AISI 304

Matte shot-blasted finish

RoHS

On request

- Various metric size fasteners and kit packaging

Cabinet U-handles GN 427 and GN 427.5 are manufactured from a bent aluminum / stainless steel profile.

see also...

	Page
GN 425 Cabinet U-Handles (Aluminum / Stainless Steel)	QVX

Technical Information

Load Capacity Information	QVX
Stainless Steel Characteristics	QVX

How to order (Aluminum)

GN 427-12-120-SR

- Handle diameter b**
- Length l**
- Finish**

How to order (Stainless steel)

GN 427.5-12-180

- Handle diameter b**
- Length l**

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4

