




Metric

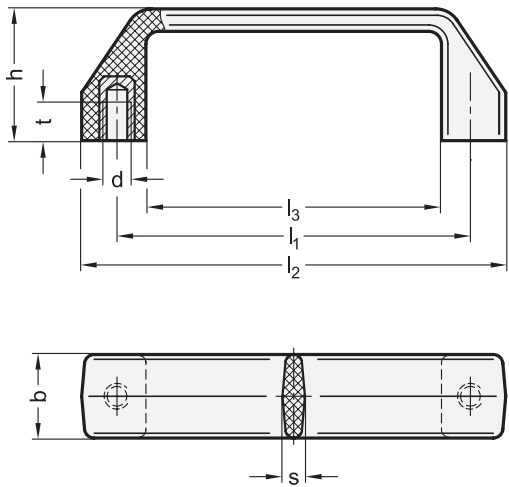

elesa
Original design M.543 / M.543-p

Metric table

2

3

Dimensions in: millimeters / inches

l ₁	d	EN 528.1 Material / Color PA PP				EN 528.4 Material / Color PA		b	h	l ₂	l ₃	s	t min.
94 -1 3.70 -0.04	M 6	SW	OR	-	-	-	-	21 0.83	36 1.42	107 4.21	79 3.11	6 0.24	10 0.39
105 ±0.5 4.13 ±0.02	M 5	SW	OR	-	-	-	-	23 0.91	37 1.46	120 4.72	90 3.54	7 0.28	10 0.39
105 ±0.5 4.13 ±0.02	M 6	SW	OR	-	-	-	-	23 0.91	37 1.46	120 4.72	90 3.54	7 0.28	10 0.39
117 ±0.5 4.61 ±0.02	M 6	SW	OR	SW	SW	OR	OR	25 0.98	38 1.50	134 5.28	102 4.02	7.5 0.30	12 0.47
117 ±0.5 4.61 ±0.02	M 8	SW	OR	-	-	-	-	25 0.98	38 1.50	134 5.28	102 4.02	7.5 0.30	12 0.47
132 ±0.5 5.20 ±0.02	M 8	SW	OR	-	-	-	-	26 1.02	45 1.77	150 5.91	116 4.57	8 0.31	13 0.51
179 ±1 7.05 ±0.04	M 8	SW	OR	-	SW	OR	OR	28 1.10	51 2.01	200 7.87	160 6.30	9 0.35	13 0.51
179 ±1 7.05 ±0.04	M 10	SW	OR	-	-	-	-	28 1.10	51 2.01	200 7.87	160 6.30	9 0.35	13 0.51

Specification

Handle

- Plastic, Polyamide
 - Glass fiber reinforced
 - Operating temperature -22 °F to 266 °F (-30 °C to 130 °C)
 - Black, RAL 9005, matte finish
 - Orange, RAL 2004, matte finish
- Plastic, Polypropylen
 - Glass fiber reinforced
 - Operating temperature -4 °F to 212 °F (-20 °C to +100 °C)
 - Black, RAL 9005, matte finish

- PA

● SW

● OR
- PP

● SW

EN 528.1

Tapped inserts

Brass

EN 528.4

Threaded studs

Steel, zinc plated

RoHS

On request

- Various metric size fasteners and kit packaging

Cabinet U-handles EN 528.1, type PP (Polypropylene) are less viable from a mechanical and thermal standpoint, but price wise they are more economical and are quite adequate for many applications. Resistant to solvents, oils, grease and other chemical agents.

see also...	Page
EN 528 Cabinet U-Handles (Plastic, Mounting from the Operator's Side)	QVX
GN 728 Economical Cabinet U-Handles (Aluminum, Mounting from the Back or the Operator's Side)	QVX
GN 728.5 Economical Cabinet U-Handles (Stainless Steel, Mounting from the Back or the Operator's Side)	QVX

Technical Information

Strength Values	QVX
Plastic Characteristics	QVX

How to order (With tapped inserts)		1	Material
		2	Length l ₁
		3	Thread d
		4	Color
EN 528.1-PP-117-M6-SW			

How to order (With threaded stud)		1	Material
		2	Length l ₁
		3	Thread d
		4	Color
EN 528.4-PA-179-M8-OR			