


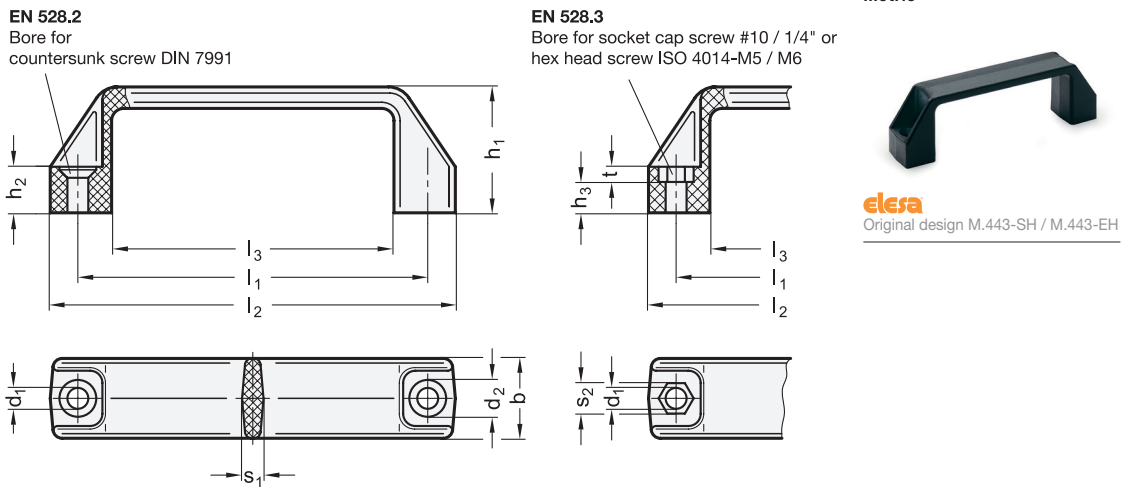

Metric table

Dimensions in: millimeters / inches												
l₁	b	d₁	d₂	h₁	h₂	h₃	l₂	l₃	s₁	s₂	t	
EN 528.2	EN 528.3											
94 -1 3.70 -0.04	94 -1 3.70 -0.04	21 0.83	5.5 0.22	10 0.39	38 1.50	13 0.51	7 0.28	109 4.29	74 2.91	6 0.24	8 0.31	6 0.24
117 ±1 4.61 ±0.04	117 ±1 4.61 ±0.04	26 1.02	6.5 0.26	12 0.47	41 1.61	15 0.59	9 0.35	137 5.39	93 3.66	7 0.28	10 0.39	6 0.24
122 ±1 4.80 ±0.04	122 ±1 4.80 ±0.04	26 1.02	6.5 0.26	12 0.47	41 1.61	15 0.59	8.5 0.33	142 5.59	100 3.94	7 0.28	10 0.39	6.5 0.26
140 ±1 5.51 ±0.04	140 ±1 5.51 ±0.04	27 1.06	6.5 0.26	12 0.47	46 1.81	16 0.63	9.5 0.37	160 6.30	113 4.45	7 0.28	10 0.39	6.5 0.26
150 ±1 5.91 ±0.04	150 ±1 5.91 ±0.04	27 1.06	6.5 0.26	12 0.47	47 1.85	17 0.67	10.5 0.41	172 6.77	125 4.92	7 0.28	10 0.39	6.5 0.26
160 ±1 6.30 ±0.04	160 ±1 6.30 ±0.04	28 1.10	6.5 0.26	12 0.47	50 1.97	17 0.67	10.5 0.41	179 7.05	132 5.20	7 0.28	10 0.39	6.5 0.26
179 ±1 7.05 ±0.04	-	28 1.10	6.5 0.26	12 0.47	50 1.97	17 0.67	-	197 7.76	151 5.94	7.5 0.30	-	-

Specification

Plastic, Polyamide
Glass fiber reinforced
• Operating temperature
-22 °F to +266 °F (-30 °C to +130 °C)
• Black, RAL 9005, matte finish

RoHS

On request

• Various metric and inch size fasteners and kit packaging

Technical Information

Strength Values
Plastic Characteristics

1

3

PA

● SW

Page

QVX

QVX

- Cabinet U-handles EN 528.2 are resistant to solvents, oils, grease and other chemical agents.
- see also...

EN 528 Cabinet U-Handles (Plastic, Mounting from the Operator's Side)

GN 728 Economical Cabinet U-Handles (Aluminum, Mounting from the Back or the Operator's Side)

GN 728.5 Economical Cabinet U-Handles (Stainless Steel, Mounting from the Back or the Operator's Side)

EN 528.1 Cabinet U-Handles (Plastic, Mounting from the Back)

Page

QVX

QVX

QVX

QVX

How to order (For countersunk screws)

1

2

3

EN 528.2-PA-179-SW

1

2

3

Material

Length l₁

Color

How to order (For hex head screws)

1

2

3

EN 528.3-PA-150-SW

1

2

3

Material

Length l₁

Color