
 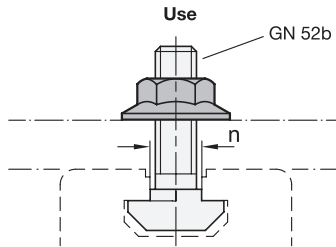



Metric

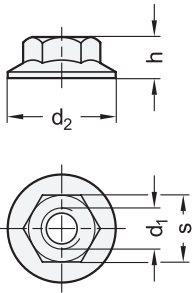

**Metric table**

Dimensions in: millimeters / inches

<b>n</b>	<b>d<sub>1</sub></b>	<b>d<sub>2</sub> ≈</b>	<b>h</b>	<b>s</b>
8 0.31	M 6	14 0.55	6 0.24	10 0.39
10 0.39	M 8	21 0.83	8 0.31	13 0.51

**Specification**

**Steel**  
Zinc plated, blue passivated finish  
RoHS

**SZ**

Collar nuts GN 53b fasten attachments and accessories in the slot of aluminum profiles, generally in combination with T-slot bolts GN 52b. The collar makes a washer unnecessary.

see also...

	Page
GN 10b Aluminum Profiles (Profile Type Light)	QVX
GN 10b Aluminum Profiles (Profile Type Heavy)	QVX

**Accessory**

GN 52b T-Slot Bolts	QVX
---------------------	-----

How to order

**GN53b-10M8-SZ**

- 1 Slot width n
- 2 Thread d<sub>1</sub>
- 3 Material / Finish

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10