


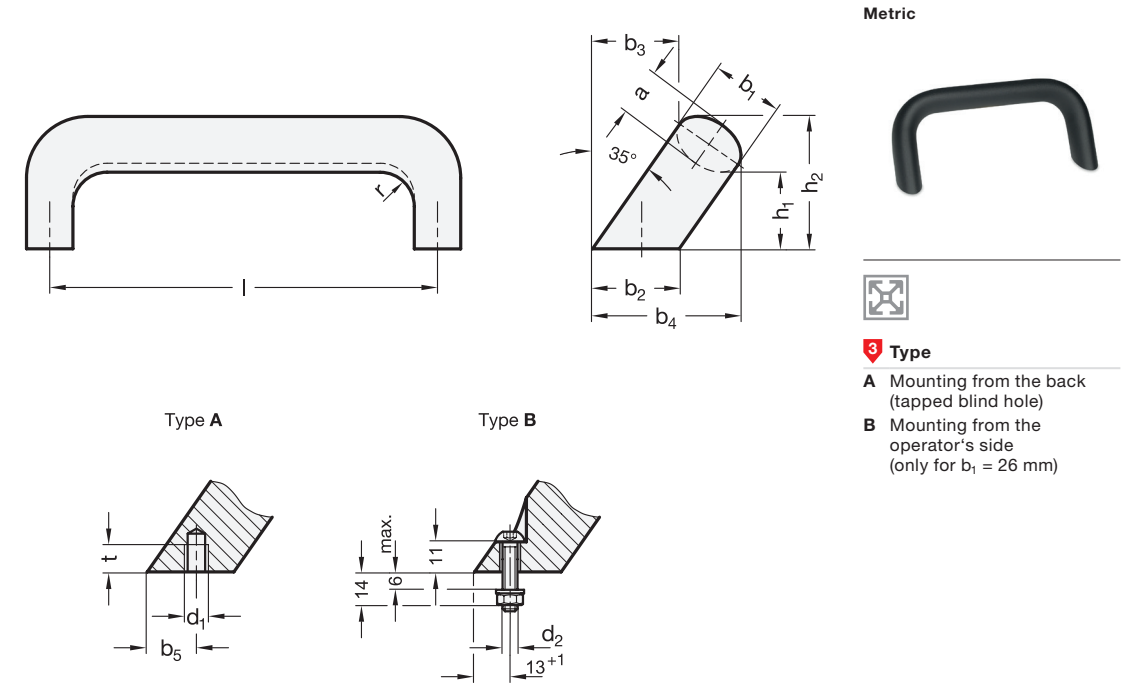

Metric table

Dimensions in: millimeters / inches												
b ₁	Length l ±0.25	a	b ₂	b ₃	b ₄	b ₅ +1	d ₁ Type A	d ₂ Type B	h ₁	h ₂	r	t min.
20 0.79	112 4.41	13 0.51	24 0.94	32 1.26	50 1.97	13.5 0.53	M 6	-	32 1.26	48 1.89	13 0.51	10 0.39
20 0.79	128 5.04	13 0.51	24 0.94	32 1.26	50 1.97	13.5 0.53	M 6	-	32 1.26	48 1.89	13 0.51	10 0.39
26 1.02	128 5.04	17 0.67	32 1.26	34 1.34	57 2.24	18 0.71	M 8	M 6	34 1.34	54 2.13	17 0.67	12 0.47
26 1.02	160 6.30	17 0.67	32 1.26	34 1.34	57 2.24	18 0.71	M 8	M 6	34 1.34	54 2.13	17 0.67	12 0.47

Specification

4

Handle

Aluminum

• Powder coated

- Black, RAL 9005, textured finish

- Silver, RAL 9006, textured finish

- Anodized finish, natural color

- Plain, tumbled finish

● SW

● SR

● EL

○ BL

Fastening set (Type B)

Steel, zinc plated, blue passivated finish

• Socket button head screws ISO 7380-M6-25

• Hex nuts ISO 4032-M6

• Washers DIN 125

RoHS

Angled cabinet U-handles GN 565.2 are manufactured from a bent aluminum profile and have excellent stability and ergonomic design.

The 35° angled contact surface allows improved access even in tight spaces such as corners.

For type B, socket button head screws, hex nuts and washers are included.

see also...

Page

GN 565.7 Angled Cabinet U-Handles (Stainless Steel, Mounting from the Back)

QVX

GN 425.1 Cabinet U-Handles (Offset Round Steel / Aluminum / Stainless Steel)

QVX

GN 426.1 Cabinet U-Handles (Offset Round Aluminum)

QVX

EN 630.1 Off-Set Open U-Handles (Plastic)

QVX

Technical Information

Product Family Standard Parts for Profile Systems

QVX

Load Capacity Information

QVX

How to order

1

Handle width b₁

2

Length l

3

Type

4

Finish

GN 565.2-26-128-B-SW