




Metric

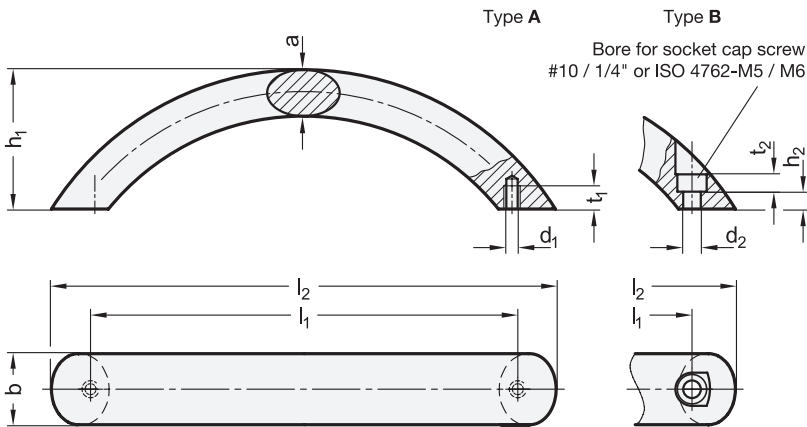

SS Stainless Steel

3 Type

- A** Mounting from the back (tapped blind hole)
- B** Mounting from the operator's side

Metric table

b		l₁	a	d₁	d₂	h₁	h₂	l₂ ≈	t₁ min.	t₂
GN 565.4	GN 565.9									
20 0.79	20 0.79	160 6.30	13 0.51	M 6	5.3 0.21	50 1.97	5 0.20	185 7.28	8 0.31	5 0.20
20 0.79	20 0.79	192 7.56	13 0.51	M 6	5.3 0.21	50 1.97	5 0.20	221 8.70	8 0.31	5 0.20
26 1.02	-	160 6.30	17 0.67	M 8	6.4 0.25	57 2.24	6 0.24	190 7.48	11 0.43	6 0.24
26 1.02	-	192 7.56	17 0.67	M 8	6.4 0.25	57 2.24	6 0.24	227 8.94	11 0.43	6 0.24

Dimensions in: millimeters / inches

Specification

GN 565.4

Aluminum

- Powder coated
 - Black, RAL 9005, textured finish
 - Red, RAL 3000, textured finish
 - Silver, RAL 9006, textured finish
- Anodized finish, natural color
- Plain, tumbled finish

- **SW**
- **RS**
- **SR**
- **EL**
- **BL**

GN 565.9

Stainless steel AISI 304

Matte shot-blasted finish

MT

RoHS

On request

- Various metric size fasteners and kit packaging

Arched pull handles GN 565.4 and GN 565.9 are preferably used for such applications where easy sliding of folding doors or cabinet drawers can be operated with a single finger. Their shape blends well with modern design.

see also...

	Page
GN 665 Arched Pull Handles (Aluminum, Ellipse Shaped Profile)	QVX
GN 424.1 Arched Pull Handles (Steel, Ø 10 mm)	QVX
GN 424.5 Arched Pull Handles (Stainless Steel, Ø 10 mm)	QVX

Technical Information

Load Capacity Information	QVX
Stainless Steel Characteristics	QVX

How to order (Aluminum)

GN 565.4-20-160-B-RS

- 1** Handle width b
- 2** Length l₁
- 3** Type
- 4** Finish

How to order (Stainless Steel)

GN 565.9-20-192-A-MT

- 1** Handle width b
- 2** Length l₁
- 3** Type
- 4** Finish