


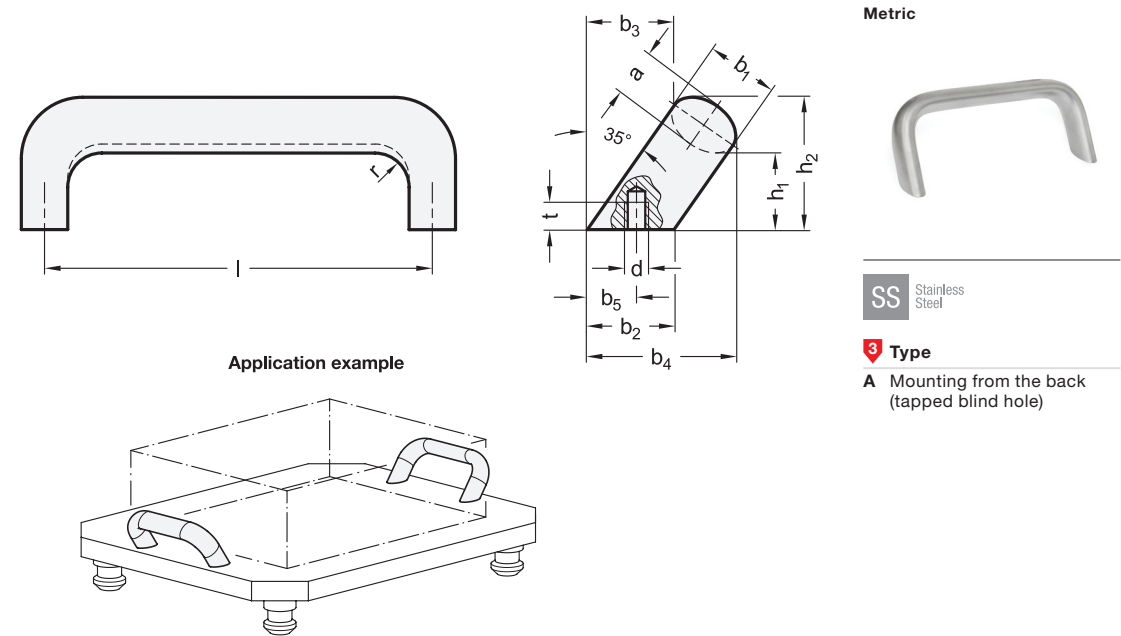

Metric table

12

Dimensions in: millimeters / inches

b ₁	Length l ±0.25	a	b ₂	b ₃	b ₄	b ₅ +1	d	h ₁	h ₂	r	t min.
20 0.79	112 4.41	13 0.51	24 0.94	32 1.26	50 1.97	13.5 0.53	M 6	32 1.26	48 1.89	13 0.51	10 0.39
20 0.79	128 5.04	13 0.51	24 0.94	32 1.26	50 1.97	13.5 0.53	M 6	32 1.26	48 1.89	13 0.51	10 0.39
26 1.02	128 5.04	17 0.67	32 1.26	34 1.34	57 2.24	18 0.71	M 8	34 1.34	54 2.13	17 0.67	12 0.47
26 1.02	160 6.30	17 0.67	32 1.26	34 1.34	57 2.24	18 0.71	M 8	34 1.34	54 2.13	17 0.67	12 0.47

Specification

Stainless steel AISI 304
Matte shot-blasted finish

RoHS

On request

• Various metric size fasteners and kit packaging

4

MT

Angled cabinet U-handles GN 565.7 are manufactured from a bent stainless steel profile and have excellent stability and ergonomic design. The 35° angled contact surface allows improved access even in tight spaces such as corners.

see also...	Page
GN 565.2 Angled Cabinet U-Handles (Aluminum, Mounting from the Back or from the Operator's Side)	QVX
GN 425.1 Cabinet U-Handles (Offset Round Aluminum / Stainless Steel)	QVX
GN 426.6 Cabinet U-Handles (Offset Round Stainless Steel)	QVX

Technical Information	
Load Capacity Information	QVX
Stainless Steel Characteristics	QVX

How to order

1234

GN 565.7-20-128-A-MT

1	Handle width b ₁
2	Length l
3	Type
4	Finish