


Metric



elesa
Original design M.2000

Application example

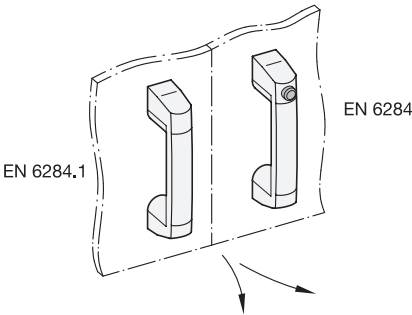

Metric table

Dimensions in: millimeters / inches								
2 l₁ ±1	3 d	b	h ₁	h ₂	l ₂	l ₃	l ₄	t
180 7.09	M 6	35 1.38	65 2.56	24 0.94	212.5 8.37	113 4.45	20 0.79	12 0.47

Specification

Handle

- Plastic, Polyamide
- Glass fiber reinforced
- Self-extinguishing, UL-94 V0
- Operating temperature
-22 °F to +248 °F (-30 °C to +120 °C)
- Black, matte finish

PA

● SW

Tapped inserts

Brass

RoHS

Cabinet U-handles EN 6284.1 are designed as a complementary handle for bridge handles EN 6284 with power switching function.

see also...

EN 6284 Cabinet U-Handles (with Power Switching Function, LED Illuminated) QVX

Technical Information

Strength Values	QVX
Plastic Characteristics	QVX

How to order	1	Material
	2	Length l ₁
	3	Thread d
	4	Color
EN 6284.1-PA-180-M6-SW		