


Metric



elesa

Original design DS-EBP.

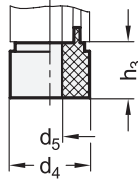

Metric table



Dimensions in: millimeters / inches

h ₃	d ₄	d ₅
18 0.71	22.5 0.89	6.5 0.26
19.5 0.77	26.5 1.04	8.5 0.33
20.5 0.81	29 1.14	9 0.35

Specification

Plastic, Polyamide (PA)

- Glass fiber reinforced
- Operating temperature
-22 °F (-30 °C) to 266 °F (130 °C)
- Black-gray, matte finish, similar RAL 7021

RoHS

Spacers EN 628.2 are accessories for bridge handles EN 628, EN 628.1 and EN 628.3.

see also...

	Page
EN 628 Bridge Handles	QVX
EN 628.1 Bridge Handles (Antimicrobial Plastic)	QVX
EN 628.3 Flexible Bridge Handles (Flexible Plastic)	QVX

Technical Information

Plastic Characteristics	QVX
Product Family Ergostyle®	QVX

How to order

EN 628.2-20.5

1 Height h₃

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4

