


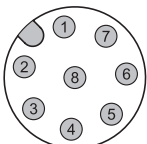

Electrical and Mechanical Characteristics

<p>Button</p> <p>Contacts</p> <p>Switching voltage</p> <p>Switching current</p> <p>Mech. life expectancy</p>	<p>1x normally open / 1x normally closed</p> <p>Max. 28 V DC / 30 V AC</p> <p>Max. 1 A</p> <p>10⁶ operating cycles</p>	
<p>LED</p> <p>Operating voltage</p> <p>Color</p>	<p>24 ± 15 % V DC</p> <p>Left - Green</p> <p>Right - Red</p>	
<p>Connection type</p> <p>Cable</p> <p>or</p> <p>Connector</p> <p>Protection class</p>	<p>PUR-cable with 2.5 m or 5 m length</p> <p>Connector M12x1, 8-pole</p> <p>IP65</p>	<p>Pin configuration and cable assignment</p>  <ul style="list-style-type: none"> 1 - white 2 - brown 3 - green 4 - yellow 5 - gray 6 - pink 7 - blue 8 - red