


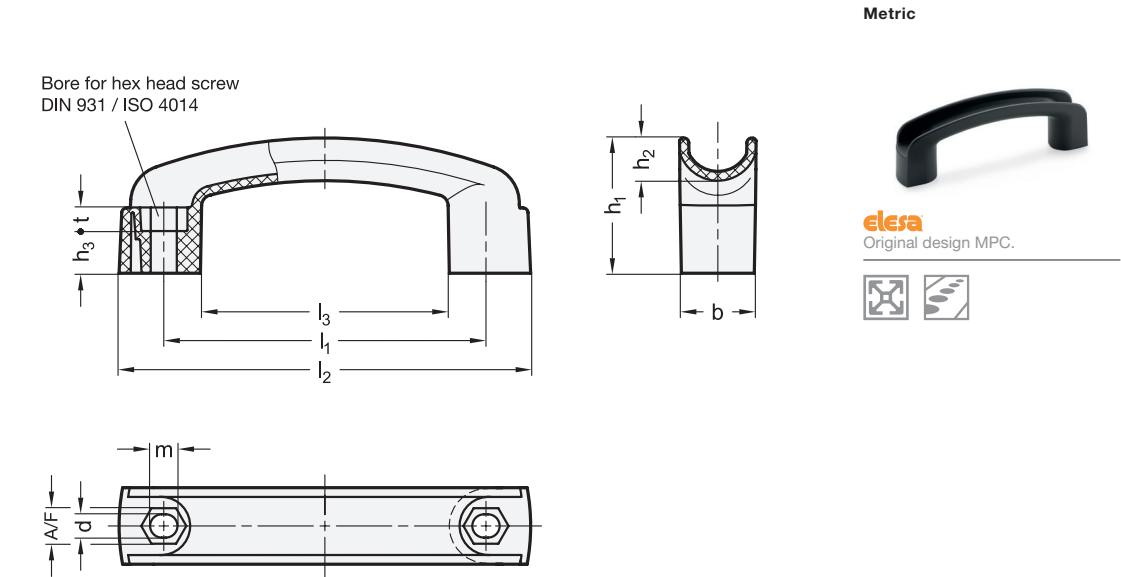

Metric table

23

Dimensions in: millimeters / inches											
l ₁		d	b	h ₁	h ₂	h ₃	l ₂	l ₃	m	A/F	t
Nominal size	Actual size										
117	118.5 ±1	6.5	28	49.5	15.5	17.5	153	93	8	10	6.5
4.61	4.665 ±0.039	0.26	1.10	1.95	0.61	0.69	6.02	3.66	0.31	0.39	0.26
117	118.5 ±1	8.5	28	49.5	15.5	15.5	153	93	10	13	8.5
4.61	4.665 ±0.039	0.33	1.10	1.95	0.61	0.61	6.02	3.66	0.39	0.51	0.33

Specification

14

Plastic, Polyamide

PA

- Glass fiber reinforced
- Operating temperature
-22 °F to +266 °F (-30 °C +130 °C)
- Black-gray, matte finish
similar to RAL 7021

SG

RoHS

The design of the cabinet U-handles EN 629.1 is based on the Ergostyle® product family.

A typical field of application for these U-handles is doors of protective enclosures on machines and fixtures.

see also...

EN 528 Cabinet U-Handles (Plastic)

EN 628 Bridge Handles (Plastic)

GN 565.1 Cabinet U-Handles (Aluminum)

Technical Information

Product Family Ergostyle®

Strength Values

Plastic Characteristics

Page

QVX

QVX

QVX

QVX

QVX

QVX

www.jwwinco.com | 1-800-877-8351

WARNING: Cancer and Reproductive Harm

www.P65Warnings.ca.gov

1