



Type A

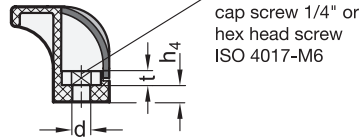

Type B

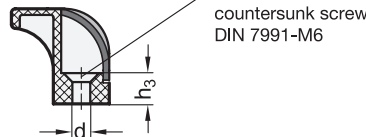

Metric



elesa

Original design ESP.



2 Type

- A Mounting with hex head screw
- B Mounting with countersunk screw

Metric table



Dimensions in: millimeters / inches

l <sub>1</sub>	b <sub>1</sub>	b <sub>2</sub>	d	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	h <sub>4</sub>	l <sub>2</sub> ±0.5	l <sub>3</sub>	t
114 4.49	35 1.38	19 0.75	6.5 0.26	33 1.30	7 0.28	11 0.43	9 0.35	93.5 3.68	74 2.91	5 0.20

Specification



Handle

- Plastic, Polyamide (PA)
- Glass fiber reinforced
- Operating temperature -22 °F to +230 °F (-30 °C to +110 °C)
- Black-gray, similar to RAL 7021, matte finish

Cover

- Plastic, Polyamide (PA)
- Black-gray, RAL 7021, shiny finish
- Orange, RAL 2004, shiny finish
- Gray, RAL 7035, shiny finish
- Yellow, RAL 1021, shiny finish
- Blue, RAL 5024, shiny finish
- Red, RAL 3000, shiny finish
- Green, RAL 6017, shiny finish

- DSG
- DOR
- DGR
- DGB
- DBL
- DRT
- DGN

RoHS

When using guards on machines and automation systems, which include double hinged doors, the off-set U-handles EN 630 completely enclosed are a safety element for operator fingers while the doors are being used. Use of a colored safety cover makes identification easier. Resistant to solvents, oils, grease and other chemical agents. The cover is included but supplied unassembled.

see also...

	Page
EN 630.1 Off-Set Open U-Handles (Plastic)	QVX

Technical Information

Product Family Ergostyle®	QVX
Strength Values	QVX
Plastic Characteristics	QVX

How to order

EN 630-114-B-DOR

- 1 Length l<sub>1</sub>
- 2 Type
- 3 Color of the cover

1.1  
1.2  
1.3  
1.4  
2.1  
2.2  
2.3  
2.4

