


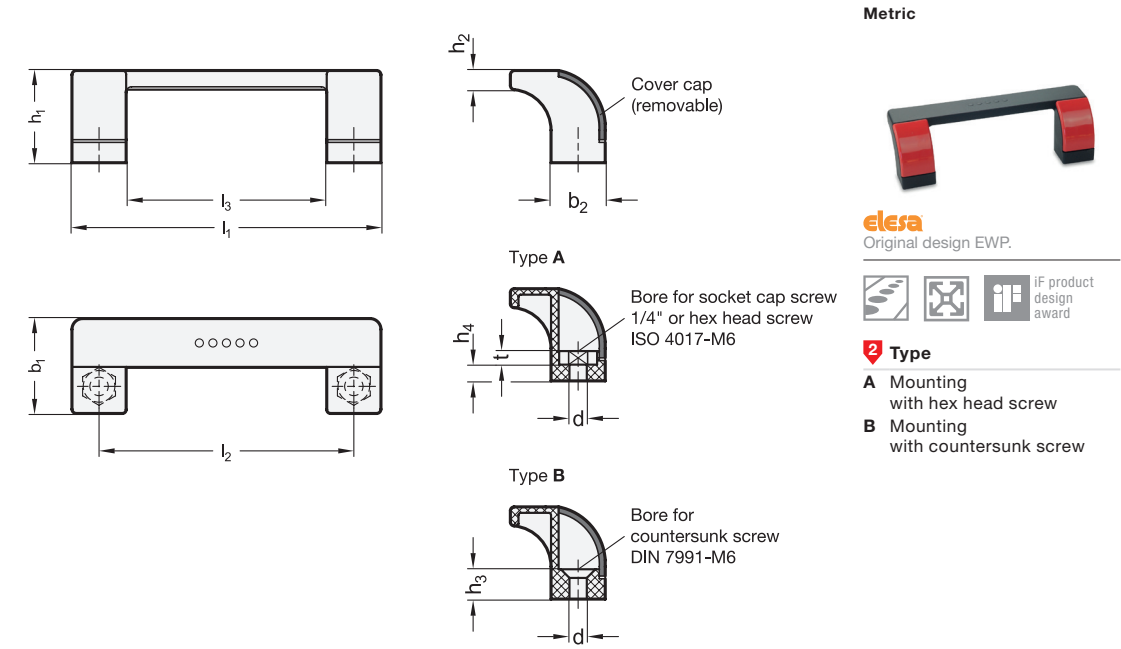

Metric table

Dimensions in: millimeters / inches										
1 l ₁	b ₁	b ₂	d	h ₁	h ₂	h ₃	h ₄	l ₂ ±0.5	l ₃	t
114 4.49	35 1.38	19 0.75	6.5 0.26	33 1.30	7 0.28	11 0.43	6 0.24	93.5 3.68	74 2.91	5 0.20

Specification

- Handle**

Plastic, Polyamide (PA)

 - Glass fiber reinforced
 - Operating temperature -22 °F to +230 °F (-30 °C to +110 °C)
 - Black-gray, similar to RAL 7021, matte finish
- Covers**

Plastic, Polyamide (PA)

 - Black-gray, RAL 7021, shiny finish
 - Orange, RAL 2004, shiny finish
 - Gray, RAL 7035, shiny finish
 - Yellow, RAL 1021, shiny finish
 - Blue, RAL 5024, shiny finish
 - Red, RAL 3000, shiny finish
 - Green, RAL 6017, shiny finish
- **DSG**
 - **DOR**
 - **DGR**
 - **DGB**
 - **DBL**
 - **DRT**
 - **DGN**

RoHS

When using guards on machines and automation systems, which include double hinged doors, use of colored covers makes identification of the off-set open U-handles EN 630.1 easier.

Resistant to solvents, oils, grease and other chemical agents.

The covers are included but supplied unassembled.

see also...	Page
EN 630 Off-Set Enclosed Safety U-Handles	QVX
GN 565.2 Angled Cabinet U-Handles (Aluminum, Mounting from the Back or the Operator's Side)	QVX
GN 425.1 Cabinet U-Handles (Offset Round Steel / Aluminum / Stainless Steel)	QVX
Technical Information	
Product Family Ergostyle®	QVX
Product Family Standard Parts for Profile Systems	QVX
Strength Values	QVX
Plastic Characteristics	QVX

How to order	1 Length l ₁
EN 630.1-114-A-DOR	2 Type
	3 Color of the cover caps