

Metric



elesa


Original design MPG-P

SS Stainless Steel

1 Type

- H** Retaining rod with internal thread
- HA** Retaining rod with threaded stud
- S** Screw with T-head
- HS** Retaining set

Application example

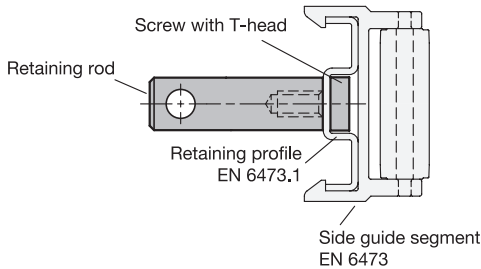

Metric table

2

Dimensions in: millimeters / inches

d ₁ Type H / HA / HS			d ₂ Type H / S / HS	Type HA	d ₃	d ₄	l ₁	l ₃	l ₄	A/F	t
D 12	D 14	D 16	M 8	M 10	6 0.24	20 0.79	100 3.94	5 0.20	17 0.67	13 0.51	20 0.79

Specification

3

Stainless steel AISI 304

NI

RoHS

Technical Information

Page

Stainless Steel Characteristics

QVX

Connecting elements EN 6473.2 fasten side guides or retaining profiles for side guide segments on conveyor sections. This also requires the use of side guide brackets EN 6476, EN 6476.2 or EN 6476.3.

see also...

	Page
EN 6471 Side Guides	QVX
EN 6472 Side Guides	QVX
EN 6473.1 Retaining Profiles	QVX
EN 6476 / EN 6476.2 / EN 6476.3	starting from page QVX

How to order (Type S)

EN 6473.2-S-NI

- 1** Type
- 3** Material

How to order (Type H / HA / HS)

EN 6473.2-HS-D14-NI

- 1** Type
- 2** Diameter d₁
- 3** Material

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10