


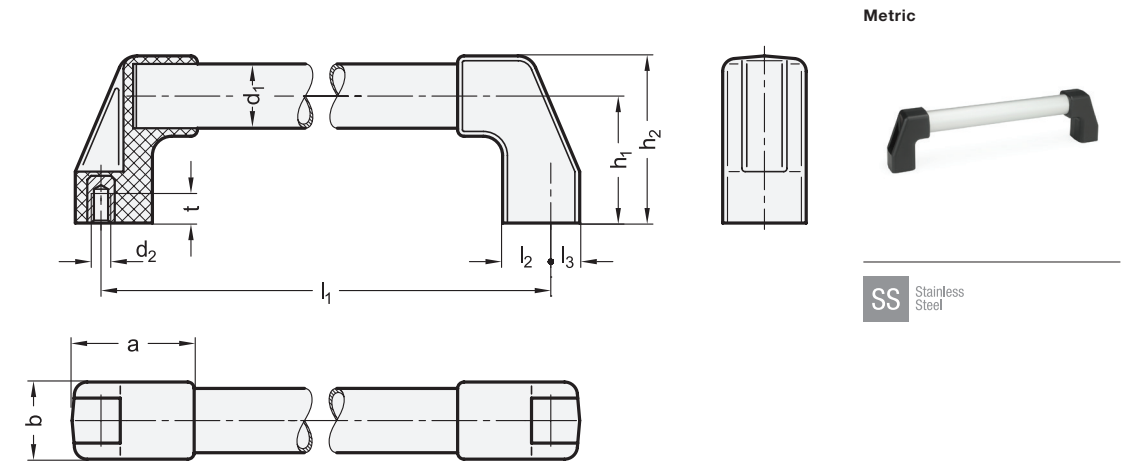

Metric table

12

Dimensions in: millimeters / inches

d ₁	l ₁ ±1								a	b	d ₂	h ₁	h ₂	l ₂	l ₃	t
30	300	350	400	500	600	700	1000	57	38	M 10	60	78	23	12	17	
1.18	11.81	13.78	15.75	19.69	23.62	27.56	39.37	2.24	1.50		2.36	3.07	0.91	0.47	0.67	

3

Specification

Handle tube

Wall thickness 1.5 mm

• Aluminum

- Powder coated

Black, RAL 9005, textured finish

● SW

- Anodized finish, natural color

● EL

• Stainless steel AISI 304

Ground, matte shiny finish

● NG

End pieces

Plastic, Polyamide (PA)

• Glass fiber reinforced

• Operating temperature up to 212 °F (100 °C)

• Black, matte finish

• Brass tapped inserts

RoHS

On request

• Special lengths

The handle tube of tubular grip handles GN 667.2 can be mounted without any further machining, allowing special lengths to be created easily.

see also...

GN 667 Tubular Grip Handles (Mounting from the Operator's Side)

QVX

Technical Information

Load Capacity Information

QVX

Plastic Characteristics

QVX

Stainless Steel Characteristics

QVX

174

 **WARNING:** Cancer and Reproductive Harm — www.P65Warnings.ca.gov

www.jwwinco.com | 1-800-877-8351

How to order

1

2

3

GN 667.2-30-1000-NG

1

2

3

Handle diameter d₁

Length l₁

Finish