


Metric




**Use**


Cover profiles

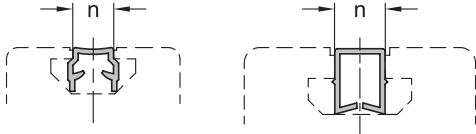

Edging profiles

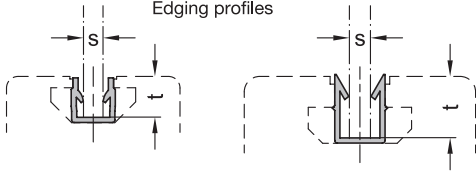

Application example

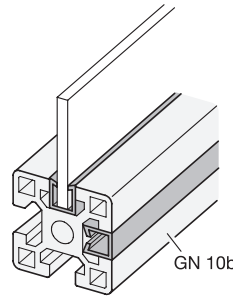

**Metric table**

<sup>1</sup> n	<sup>3</sup> Length l in meters	<sup>4</sup> Bundle Pieces	b ≈	h ≈	s Clamping range min. ... max.	t
8 0.31	2	4	10 0.39	8.5 0.33	4 ... 6	8 0.31
10 0.39	2	4	14 0.55	13 0.51	4 ... 6	11.5* 0.45

Dimensions in: millimeters / inches

\* 13.5 for aluminum profile 10b-454510L + 10b-459010L

**Specification**

Plastic, Polypropylene (PP)

Black



● KS

RoHS

Cover and edging profiles GN 70b are inserted into the slot of aluminum profiles.

When used as a cover profile, they are installed with the closed side facing out. This way, they protect the slot from dust and dirt, cover the cables and hoses in the slot and make for a visually appealing appearance.

When used as an edging profile, they are installed with the open side facing out. This allows for panel elements such as panes of glass or PMMA to be fixed directly into the groove.

Cover and edging profiles are supplied in bundles. The table shows the quantity included in each bundle.

see also...

	Page
GN 10b Aluminum Profiles (Profile Type Light)	QVX
GN 10b Aluminum Profiles (Profile Type Heavy)	QVX

**Technical Information**

Plastic Characteristics	QVX
-------------------------	-----

How to order

<sup>1</sup> <sup>2</sup> <sup>3</sup> <sup>4</sup>  
**GN 70b-10-KS-2-4**

- <sup>1</sup> Slot width n
- <sup>2</sup> Color
- <sup>3</sup> Length l
- <sup>4</sup> Bundle

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10

