




Metric

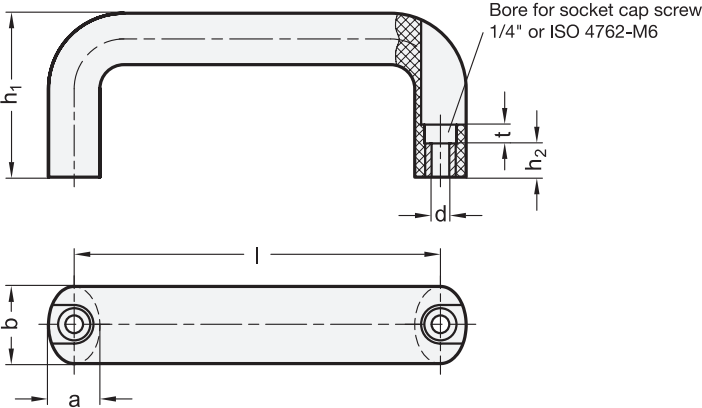

Metric table

Dimensions in: millimeters / inches						
Length l	a	b	d	h ₁	h ₂	t
86 ±0.5 3.39 ±0.02	14 0.55	23 0.91	5.4 0.21	44 1.73	15 0.59	5.5 0.22
117 ±0.5 4.61 ±0.02	16 0.63	25 0.98	6.4 0.25	49 1.93	15 0.59	6 0.24
132 ±1 5.20 ±0.04	16 0.63	26 1.02	6.4 0.25	53 2.09	15 0.59	8.5 0.33
179 ±1 7.05 ±0.04	16 0.63	27 1.06	6.4 0.25	57 2.24	15 0.59	6 0.24

Specification

Handle

- Plastic, Polypropylene (PP)
- Shock-resistant
 - Operating temperature
-4 °F to +212 °F (-20 °C to +100 °C)
 - Black, matte finish

Tapped inserts

Brass, molded-in

RoHS

On request

Various metric and inch size fasteners and kit packaging

Cabinet U-handles EN 725.1 are well known for their smooth ergonomically shaped elliptical design.
High impact strength. Resistant to solvents, oils, grease and other chemical agents.

see also...	Page
GN 565.1 Cabinet U-Handles (Aluminum)	QVX
GN 565.5 Cabinet U-Handles (Stainless Steel, Mounting from the Back or the Operator's Side)	QVX

Technical Information

Strength Values	QVX
Plastic Characteristics	QVX