


Application example

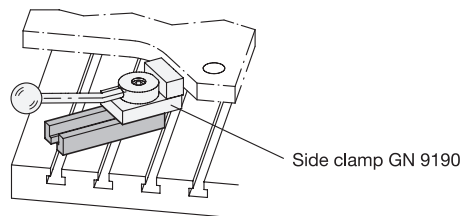

Metric table

Dimensions in: millimeters - inches

b ₁	l ₁	d	b ₂	b ₃	h ₁	h ₂	l ₂	l ₃	For side clamp slot width a		
									GN 9190	GN 9190.1	GN 9190.2
30 <i>1.18</i>	100 <i>3.94</i>	M 8	15 <i>0.59</i>	9 <i>0.35</i>	15 <i>0.59</i>	6.5 <i>0.26</i>	63 <i>2.48</i>	20 <i>0.79</i>	10 <i>0.39</i>	10 <i>0.39</i>	10 <i>0.39</i>
40 <i>1.57</i>	120 <i>4.72</i>	M 12	20 <i>0.79</i>	13 <i>0.51</i>	20 <i>0.79</i>	7.5 <i>0.30</i>	72 <i>2.83</i>	25 <i>0.98</i>	12 <i>0.47</i>	14 <i>0.55</i>	14 <i>0.55</i>
60 <i>2.36</i>	140 <i>5.51</i>	M 16	26 <i>1.02</i>	17 <i>0.67</i>	30 <i>1.18</i>	13 <i>0.51</i>	80 <i>3.15</i>	30 <i>1.18</i>	-	18 <i>0.71</i>	18 <i>0.71</i>

Specification

- Steel
 - Tempered
 - Blackened finish
- RoHS compliant

Information

Slotted support blocks GN 9190.3 are provided as an accessory for side clamps GN 9190 / GN 9190.1 / GN 9190.2.

They can also be used to fasten side clamps across the T-slot in any position.

see also...

- Side Clamps GN 9190 (with Eccentric Cam Lever) → page QVX
- Side Clamps GN 9190.1 (with Clamping Thread) → page QVX
- Side Clamps GN 9190.2 (with Support Plate) → page QVX

How to order	1	Width b ₁
	2	Length l ₁
	3	Thread d
GN 9190.3-30-100-M8		

1.1
1.2
1.3
1.4
2.1
2.2
2.3
2.4