


Inch

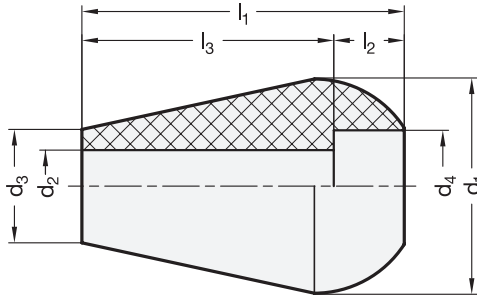

Inch table

Dimensions in: inches / millimeters

<b>d<sub>1</sub></b>	<b>d<sub>2</sub></b>	<b>d<sub>3</sub></b>	<b>d<sub>4</sub></b>	<b>l<sub>1</sub></b>	<b>l<sub>2</sub></b>	<b>l<sub>3</sub></b>
1.19 30.2	B 1/4	0.63 16	0.62 15.7	1.80 45.7	0.40 10.2	1.40 35.6
1.19 30.2	B 5/16	0.63 16	0.62 15.7	1.80 45.7	0.40 10.2	1.40 35.6
1.19 30.2	B 3/8	0.63 16	0.62 15.7	1.80 45.7	0.40 10.2	1.40 35.6

**Specification**

Plastic, Phenolic (PF)

- Operating temperature up to 300 °F (149 °C)
- Black
- With through hole

RoHS

Tapered knobs TAK can be utilized as a fixed grip knob or a revolving knob by mounting the knob via an applicable socket cap screw or, socket cap shoulder screw.

**Technical Information**

Plastic Characteristics

Page

QVX

How to order

**TAK-1.19-B1/4**

1 Handle diameter  $d_1$

2 Bore diameter  $d_2$

1.1  
1.2  
1.3  
1.4  
2.1  
2.2  
2.3  
2.4

